


Orange Peel® Rotating Shaft Guards Safety Labels

ANSI Z535.4 Compliant Warning Labels

Required for Safety Compliance!

A duty to warn and communicate a safety risk is required for most removable equipment guards. ANSI Z535.4 Warning Labels are supplied in English as standard. Custom translated Warning Labels are available by request for multi-lingual requirements. Labels are a severe duty type featuring a 2 mil polyester base material with a 5 mil clear lamination and modified acrylic adhesive backing. Labels can also be drilled and mechanically fastened using stainless steel pop rivets. All labels are suitable for -40°C to 149°C (-40°F to 300°F) temperatures, and are chemical, abrasion, and fade resistant. Orange Peel Safety Labels can be purchased through a Rexnord Representative or a Rexnord Distributor; locate them at www.rexnord.com.

Coupling & Shaft Guards Belt & Chain Guards

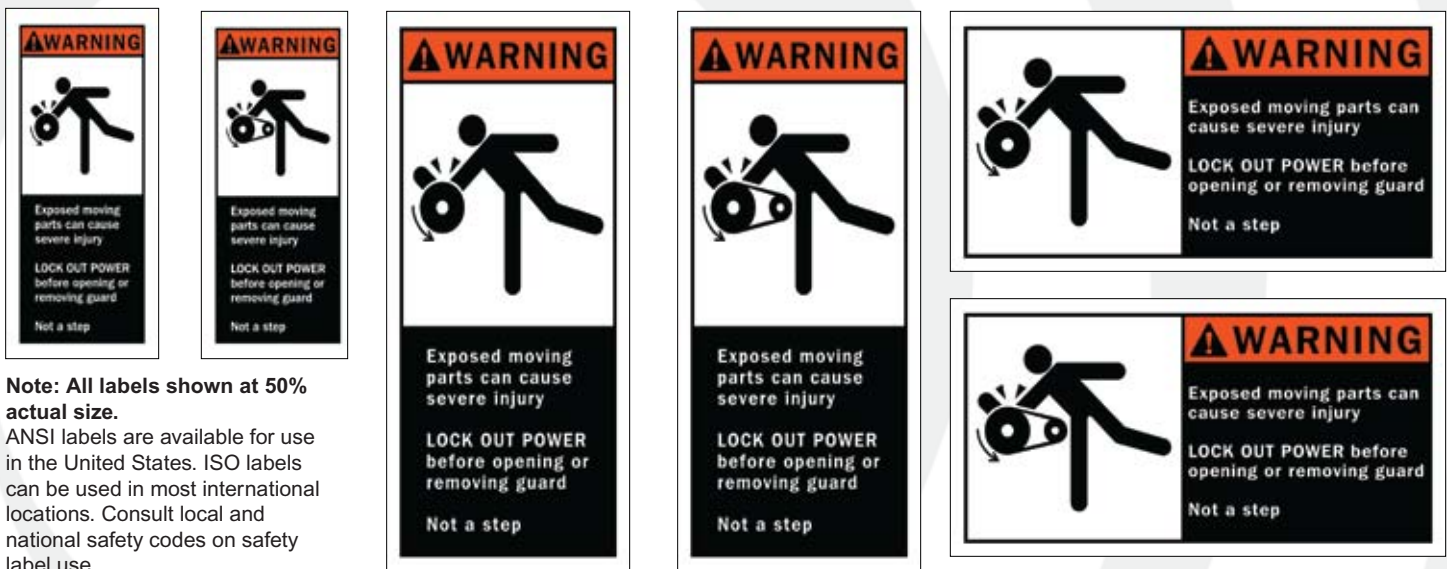

Note: All labels shown at 50% actual size.
ANSI labels are available for use in the United States. ISO labels can be used in most international locations. Consult local and national safety codes on safety label use.


SIZE	Description	Part Number
48 x 95mm/1.88" x 3.75"	ANSI Vertical Warning Label — Coupling & Shaft/English	2924286
48 x 95mm/1.88" x 3.75"	ANSI Vertical Warning Label — Belt & Chain/English	2924287
75 x 150mm/3" x 6"	ANSI Vertical Warning Label — Coupling & Shaft /English	2924288
75 x 150mm/3" x 6"	ANSI Vertical Warning Label — Belt & Chain/English	2924289
150 x 75mm/6" x 3"	ANSI Horizontal Warning Label — Coupling & Shaft /English	2924290
150 x 75mm/6" x 3"	ANSI Horizontal Warning Label — Belt &Chain/English	2924291

ISO 3864 Compliant Warning Labels

Required for Safety Compliance!

The European Machinery Directive states that the manufacturer must provide a warning for potential risks which are not evident. ISO 3864 Safety Labels are supplied in symbol based format. Labels are a severe duty type featuring a 2 mil polyester base material with a 5 mil clear lamination and modified acrylic adhesive backing. Labels can also be drilled and mechanically fastened using stainless steel pop rivets. All labels are suitable for -40°C to 149°C (-40°F to 300°F) temperatures, and are chemical, abrasion, and fade resistant. Orange Peel Safety Labels can be purchased through a Rexnord Representative or a Rexnord Distributor; locate them at www.rexnord.com.

Coupling & Shaft Guards Belt & Chain Guards

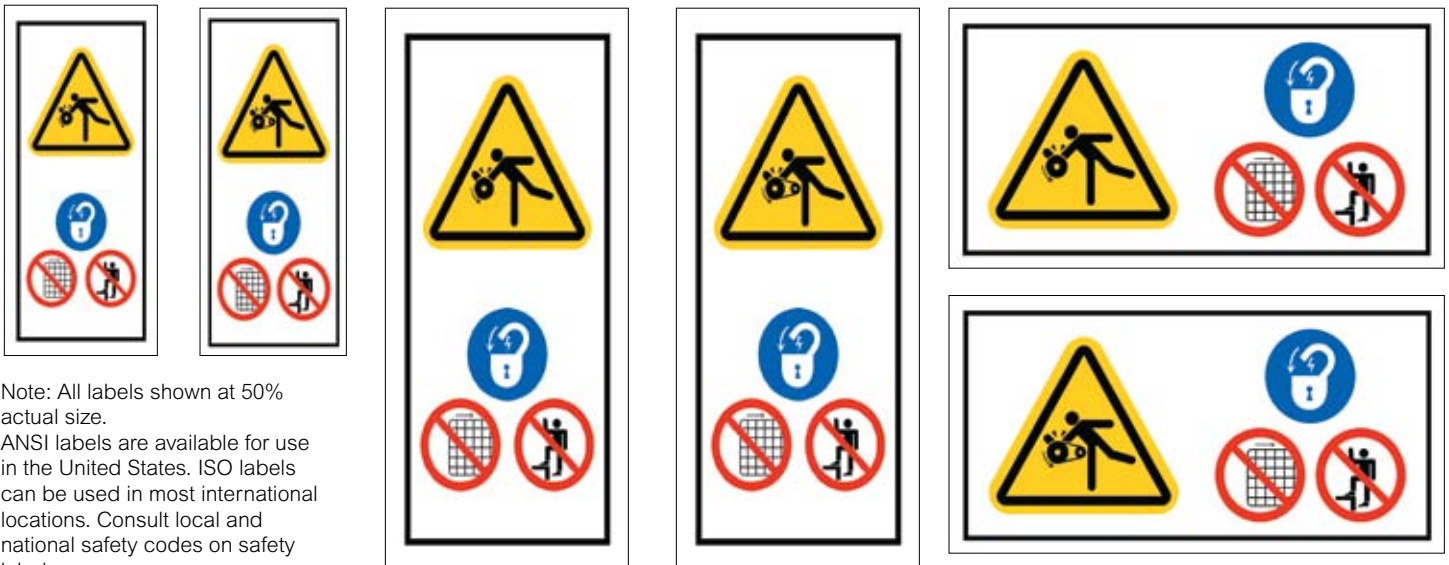

Note: All labels shown at 50% actual size.
ANSI labels are available for use in the United States. ISO labels can be used in most international locations. Consult local and national safety codes on safety label use.

SIZE	Description	Part Number
48 x 95mm/1.88" x 3.75"	ISO Vertical Safety Label — Coupling & Shaft/Symbols	2924292
48 x 95mm/1.88" x 3.75"	ISO Vertical Safety Label — Belt & Chain/Symbols	2924293
75 x 150mm/3" x 6"	ISO Vertical Safety Label — Coupling & Shaft /Symbols	2924294
75 x 150mm/3" x 6"	ISO Vertical Safety Label — Belt & Chain/Symbols	2924295
150 x 75mm/6" x 3"	ISO Horizontal Safety Label — Coupling & Shaft /Symbols	2924296
150 x 75mm/6" x 3"	ISO Horizontal Safety Label — Belt & Chain/Symbols	2924297