


## Introduction

This literature applies to Model A, B and C standard gear drives with ratings, speeds, ratios, and dimensions as catalogued in current Falk™ selection guides. Type “AXV” drives have vertical axis high and low speed shafts. The low speed shafts may be configured up (U) or down (D). Type “AXVQ” drives have a vertical high speed shaft and a vertical hollow low speed shaft. Refer to Rexnord for all specials and modifications.


- IDENTIFY DRIVE** — Give complete data shown on drive nameplate. Also, give reference numbers, Falk™ part numbers, and name of parts required. Drawings and reference numbers are representative of all sizes and the actual parts may not agree in exact detail for each drive size. Complete nameplate data and parts reference number will assure receipt of correct parts.

The numerical designation stamped on the nameplate completely identifies all parts used in the drive. All drives with exactly the same nameplate markings have interchangeable rotating elements.


## Sample Nameplate

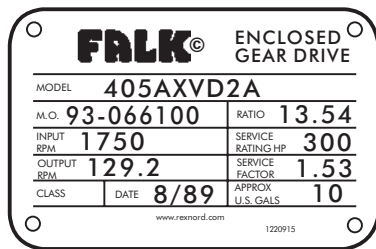

## Drive Identification

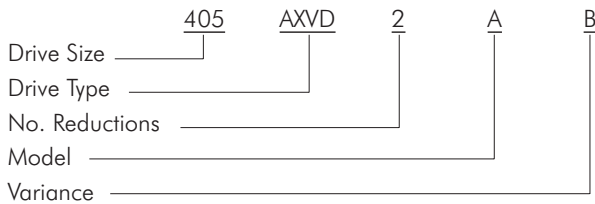

- IDENTIFY INDIVIDUAL PARTS** — Use exploded view on Page 2 to determine Ref. No. of required parts.

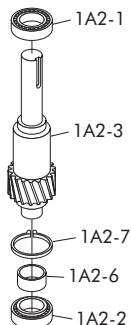

Ref. No.	Part Description
1A2-1	Bearing
1A2-2	Bearing
1A2-3	Pinion & Shaft
1A2-6	Spacer
1A2-7	Retaining Ring

**NOTE:** It is recommended that the shaft seals be replaced whenever it becomes necessary to disturb a seal in the process of disassembling a drive. New Shim-gaskets are recommended to prevent oil leakage and in some cases necessary to adjust internal running clearances. Shim-gaskets are available only in kits; see Ref. No. 100.

**PINION-SHAFT-BEARING ASSEMBLIES** — With today’s production procedures, Rexnord can normally furnish a total rotating assembly more economically than if a customer purchases individual parts, disassembles the old parts, and reassembles using some new and some old parts. Falk™ replacement assemblies also reduce down time and always consist of all new parts.

**FASTENERS** — Fasteners are sold in sets for a specific item, i.e. four for an end cover, eight for a low speed seal cage, etc. Fasteners describe cap screws, bolts, studs, nuts, and lock washers as required.

**RATIO CHANGE** — Refer complete information to Factory.

**SHAFT COUPLINGS** — Refer to coupling parts guide and price list.

- HOW TO USE THIS GUIDE** — Use the Part Ref. No. (Step 2) and the drive Model No. (Step 1) to determine the part description and use this information to order the required parts.

- ORDER REPLACEMENT** — Place your order with your local Rexnord Account Executive or Distributor. If you need assistance call the number below.

## Bearing & Seal Identification

Refer to the exploded views on Page 2 to identify the bearings and oil seals by the parts list Reference Number. Then refer to Tables 2 thru 5, Pages 3 and 4, to determine the Manufacturer and Manufacturer’s part number.


## Corrosion Protection & Storage

**CAUTION:** Follow guidelines below to avoid damage to parts.

- For domestic or indoor storage, Factory provides standard 24 month protection as boxed or optional 24 month protection for individual parts.
- For export or outdoor storage, Factory provides optional 18 month protection.

**CAUTION:** This protection does not cover exposure to elements such as standing water, etc.

### Parts Diagram

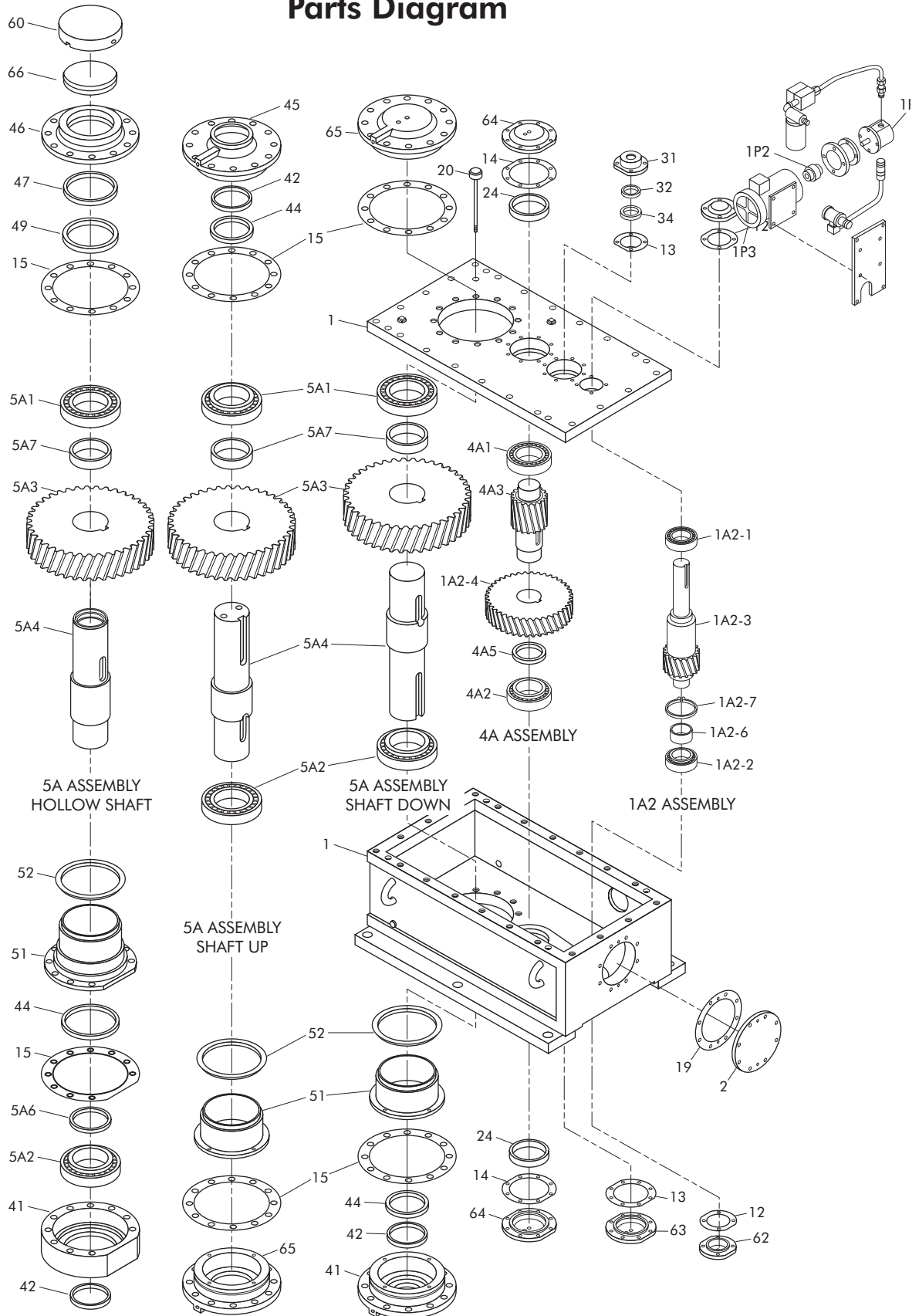

**TABLE 1 — Parts List**

Ref. No.	Part Description	Drive Type
1	Housing-Cover & Base	AXV, AXVQ
2	End Cover	AXV, AXVQ
12	Shim-Gasket	AXV, AXVQ
13	Shim-Gasket	AXV, AXVQ
14	Shim-Gasket	AXV, AXVQ
15	Shim-Gasket	AXV, AXVQ
19	Shim-Gasket	AXV, AXVQ
20	Dipstick	AXV, AXVQ
24	Spacer	AXV, AXVQ
31	Seal Cage	AXV, AXVQ
32	Seal	AXV, AXVQ
34	Seal	AXV, AXVQ
41	Bearing/Seal Cage	AXV, AXVQ
42	Seal	AXV, AXVQ
44	Seal	AXV, AXVQ
45	Bearing/Seal Cage	AXV
46	Seal Cage	AXVQ
47	Seal	AXVQ
49	Seal	AXVQ
51	Oil Dam	AXV, AXVQ
52	Seal	AXV, AXVQ
60	Shaft Cover	AXVQ
62	Shaft Cover	AXV, AXVQ
63	Shaft Cover	AXV, AXVQ
64	Shaft Cover	AXV, AXVQ
65	Bearing/Seal Cage	AXV
66	Thrust Plate	AXVQ
100	Shim-Gasket Kit (Inc. Ref. Nos. 12, 13, 14, 15 & 19)	AXV, AXVQ
<b>HIGH SPEED SHAFT ASSEMBLY</b>		
1A2	Shaft Assembly (Inc. Ref. Nos. 1A2-1, 1A2-2, 1A2-3, 1A2-6, & 1A2-7)	AXV, AXVQ
1A2-1	Bearing	AXV, AXVQ
1A2-2	Bearing	AXV, AXVQ
1A2-3	Pinion & Shaft	AXV, AXVQ
1A2-4	Gear (Inc. with Ref. 4A)	AXV, AXVQ
1A2-6	Spacer	AXV, AXVQ
1A2-7	Retaining Ring	AXV, AXVQ
<b>EXTERNAL LUBRICATION PUMP</b>		
1P	Pump Assembly	AXV, AXVQ
1P1	Pump	AXV, AXVQ
1P2	Coupling	AXV, AXVQ
1P3	Motor	AXV, AXVQ
<b>LOW SPEED PINION ASSEMBLY</b>		
4A	Shaft Assembly (Inc. Ref. Nos. 4A1 thru 4A5 & 1A2-4)	AXV, AXVQ
4A1	Bearing	AXV, AXVQ
4A2	Bearing	AXV, AXVQ
4A3	Pinion & Shaft	AXV, AXVQ
4A5	Spacer	AXV, AXVQ
<b>LOW SPEED SHAFT ASSEMBLY</b>		
5A	Shaft Assembly (Inc. Ref. Nos. 5A1 thru 5A7)	AXV, AXVQ
5A1	Bearing	AXV, AXVQ
5A2	Bearing	AXV, AXVQ
5A3	Gear	AXV, AXVQ
5A4	Shaft	AXV, AXVQ
5A6	Spacer (Size 405 only)	AXVQ
5A7	Spacer	AXV, AXVQ

**TABLE 2 — Oil Seals/Falk™ Part Numbers**

DRIVE SIZE	Reference No. & Type								
	32	34	42		44		47	49	52
	AXV & AXVQ	AXV & AXVQ	AXV	AXVQ	AXV	AXVQ	AXVQ	AXVQ	AXV & AXVQ
405	912993	912994	913000	912816	913001	912767	913001	912833	2912858
425	913012	913013	913016	912767	913017	912827	913017	912767	2913534
445	912995	912996	913004	912578	913005	912580	913005	912578	2912448
465	912997	912998	913023	912580	913024	912550	913024	912940	2912803
485	913014	913015	2913169	912550	2913170	912808	2913170	2913168	2913172
505	912999	912310	913025	912809	912769	912905	912809	2913977	2917215
535	913002	913003	2918393	2900932	2903222	912842	2900932	2913542	2914611
555	913021	913022	912550	912903	913034	2918744	912902	912903	2918891

**TABLE 3 — Bearings/Falk™ Part Numbers**

DRIVE SIZE	Reference No. & Type			
	1A2-1/1A2-2	4A1/4A2	5A1/5A2 AXV	5A1/5A2 AXVQ
405	921855	921899	921674	921331
425	921771 †	921552	921881	921759
445	921678	921443	921439	2912892
465	921443	921541	2912611	2912802
485	921541	921470	921788	2913166
505	921470	921481	921791	2917124
535	921646	921901	2918718 ▲	2918385
555	921481	921906	2918739	2918740 ♣

† Use 921895 for ratios 22.86 thru 25.00.

▲ Use 921794 for Reference No. 5A2.

♣ Use 2918741 for Reference No. 5A2.

**TABLE 4 — Seal Manufacturers' Part Numbers**

Falk™ Part No.	Manufacturers' No.
912310	CRWH49991(V)
912550	CRWH1-115021
912578	JM/16554-LUP
912580	NATJ-1109
912767	CRWH77540
912769	CR92536
912808	CR1300570
912809	CR122580
912816	CR70016
912827	CRWH85009
912833	CR70052
912842	JM10516LUPHL15 ▲
912902	CR1500240
912903	CR1500380
912905	CR1375240
912940	NAT417020
912993	CRWH24914(V)
912994	CRWH24984(V)
912995	CRWH34892(V)
912996	JM/8821LPD-H5/L16(V)
912997	CRWH39932(V)
912998	CRWH39996(V)
912999	JM/9629LUP-H5/L16(V)
913000	CRWH52447(V)
913001	CRWH52489(V)
913002	CRWH54934(V)
913003	CRWH54974(V)
913004	CRWH64998(V)
913005	JM/8950LUP-H5/L16(V)
913012	JM/5961LUP-H5/L16(V)
913013	CRWH29958(V)
913014	CRWH44973(V)
913015	JM/11709LUP-H5/L16(V)
913016	CRWH57522(V)
913017	CRWH57523(V)
913021	JM/9514LUP-H5/L16(V)
913022	JM/0600-19591LUP-H5/L16
913023	JM/12094LUP
913024	JM/8951LUP
913025	NATIONAL416257
913034	JM/10509H115LUP
2900932	CR1350250HSD1
2903222	CR105051
2912448	CR402750
2912803	CR403250
2912858	CR402002
2913168	CRWH115041
2913169	CRWH80010
2913170	CRWH180037
2913172	CR403500
2913534	CR402500
2913542	CR1350542HDS-Z
2913977	CR1225525HDS-Z
2914611	CR404500
2917215	CR403750
2918393	CR1050240-HDSI
2918744	CR1625243-HS52
2918891	CR405000

▲ Manufacturer is J.M. Clipper.

**TABLE 5 — Bearing Manufacturers' Part Numbers**

Falk™ Part No.	Manufacturers' No.
921331	TIMHM237545/HM237510
921439	TIMHM237535/HM237510
921443	TIMHH221449/HH221410
921470	TIMHH228349/HH228310
921481	TIMHH234048/HH234010
921541	TIMHH224346/HH224310
921552	TIMHH421246C/HH421210
921646	TIMHH231649/HH231610
921674	TIM95528/95925
921678	TIM850/832
921759	TIMJHM840449/JHM840410
921771	TIMJLM714149/JLM714110
921788	TIMH242649/H242610
921791	TIMH247549/H247510
921794	TIM681/672
921855	TIM5584/5535
921881	TIM99575/99100
921895	TIMH715346/H715311
921899	TIM843/832
921901	TIMHH437549/HH437510
921906	TIMNP180202/NP513983
2912611	TIMH239649/H239610
2912802	TIMEE275100/EE275155
2912892	TIMEE130902/EE131400
2913166	TIMEE722115/EE722185
2917124	TIMH8590049/H859010
2918385	TIMNPR08-9386
2918718	TIMEE295110/EE295193
2918739	TIMHH258248/HH258210
2918740	TIMM268730/M268710
2918741	TIMNPR08-9500