



Key Industries:

- Air Handling
- Aggregates
- Construction
- Forestry
- Mining
- Steel
- Wastewater Management

Housing Options:

- Pillow Blocks
- 4-Bolt Flange Blocks
- Piloted Flange Blocks
- Cartridge Blocks
- Take-Up Blocks

Shaft Sizes:

1 15/16" – 6 15/16"

Mounting Type:

- Single Set Collar
- Double Set Collar
- Eccentric Collar
- Adapter Mount

General Bearing Information:

- TGIC Polyester Powder Coated Housings
- Super Finished Raceways
- Larger than Standard Rollers
- Field Interchangeable Seal Options
- Adjustable Clearance

Rex 6000 Series SHURLOK Adapter Mounted Roller Bearing

Increase your operation's efficiency and profitability by reducing installation errors, maintenance costs, and downtime. The innovative Rex® 6000 Series SHURLOK® Adapter Mounted Roller Bearing requires less lubrication and is ideal for ISO 14000 compliance.

The bearing's rugged and adaptable design makes it excellent for mining, aggregate production, forest products, and other demanding applications.

Shaft mounting errors are a thing of the past with the breakthrough proprietary Spyglass™ Optical Strain Sensor (OSS) technology.

A positive locking feature and single housing construction also provide easy installation and removal, and enable use of inexpensive commercial grade shafting.

Shurlok Mounts are available in many rexnord housings for shaft sizes from 1 15/16 inches to 1 15/16 inches. They also have three interchangeable seal options and several auxiliary cap seal configurations to meet each unique application's needs.

ZA 6000




VS

Imperial®



- 25 percent greater shaft grip (on 2 7/16 shaft size) means less vibration and maintenance.
- Quick release feature allows easy removal for maintenance, plus the adapter assembly with Spyglass OSS can be reused.
- Positive Locking System maintains shaft mount tightness, eliminating the need for later mounting inspections.
- Spyglass OSS takes the guesswork out of installation, eliminating damage to the shaft caused by loose mounting.

ZAF 6000

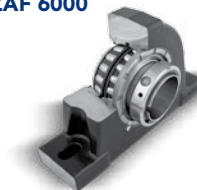

VS

SAF



- Spyglass OSS eliminates the subjectivity of determining shaft mounting tightness.
- Rugged one-piece housing decreases installation/removal time by as much as four times versus SAF models.
- Factory pre-lubricated elements require four times less annual lubrication than SAF models - ISO 14000 friendly.
- Factory pre-set clearances. Solid housed units with factory pre-set clearances reduce installation time by up to four times.

Super-finished Raceways
Provide a cool running, quiet, high speed and high load capacity bearing

Self Aligning Spherical Roller Bearing
Provides a total of four degrees static and dynamic misalignment

Auxiliary End Caps & Four Field Interchangeable Seal Options
Ensures long bearing life through a full range of applications



Roller Elements
Are precision ground and super finished to provide longer bearing life


Adapter Sleeve Assembly
Allows easy installation/removal, plus enables use of commercial grade shafts

Positive Locking System
Allows minimal vibration during operation, therefore not requiring scheduled inspections for snugness of mountings

Spyglass™ Optical Strain Sensor (OSS) Technology
Reduces installation errors



Easy Installation
Simply tighten the collar until the Spyglass shows proper indication

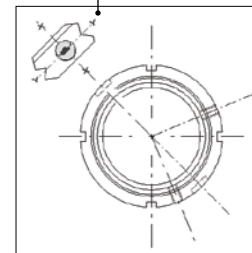

Rex 6000 Series SHURLOK Roller Bearings are also available in these housings:



Rex 6000 Series Roller Bearing Interchange Examples

Shaft Size Inches	# of Bolts	Rex 6000 Series		Dodge Imperial	
		Fixed	Floating	Fixed	Floating
1-15/16	2	ZA-6115	ZAS-6115	P2B-IP-115R	P2B-IP-115RE
1-15/16	4	ZA-6115-F	ZAS-6115-F	P4B-IP-115R	P4B-IP-115RE
2-13/16	2	ZA-6203	ZAS-6203	P2B-IP-203R	P2B-IP-203RE
2-13/16	4	ZA-6203-F	ZAS-6203-F	P4B-IP-203R	P4B-IP-203RE
2-3/8	2	ZA-6206	ZAS-6206	P2B-IP-206R	P2B-IP-206RE
2-3/8	4	ZA-6206-F	ZAS-6206-F	P4B-IP-206R	P4B-IP-206RE
2-7/16	2	ZA-6207	ZAS-6207	P2B-IP-207R	P2B-IP-207RE
2-7/16	4	ZA-6207-F	ZAS-6207-F	P4B-IP-207R	P4B-IP-207RE
2-11/16	2	ZA-6211	ZAS-6211	P2B-IP-211R	P2B-IP-211RE
2-11/16	4	ZA-6211-F	ZAS-6211-F	P4B-IP-211R	P4B-IP-211RE
2-3/4	2	ZA-6212	ZAS-6212	P2B-IP-212R	P2B-IP-212RE
2-3/4	4	ZA-6212-F	ZAS-6212-F	P4B-IP-212R	P4B-IP-212RE
2-15/16	2	ZA-6215	ZAS-6215	P2B-IP-215R	P2B-IP-215RE
2-15/16	4	ZA-6215-F	ZAS-6215-F	P4B-IP-215R	P4B-IP-215RE
3-3/16	2	ZA-6303	ZAS-6303	P2B-IP-303R	P2B-IP-303RE
3-3/16	4	ZA-6303-F	ZAS-6303-F	P4B-IP-303R	P4B-IP-303RE
3-7/16	2	ZA-6307	ZAS-6307	P2B-IP-307R	P2B-IP-307RE
3-7/16	4	ZA-6307-F	ZAS-6307-F	P4B-IP-307R	P4B-IP-307RE
3-11/16	2	ZA-6311	ZAS-6311	P2B-IP-311R	P2B-IP-311RE
3-11/16	4	ZA-6311-F	ZAS-6311-F	P4B-IP-311R	P4B-IP-311RE
3-15/16	2	ZA-6315	ZAS-6315	P2B-IP-315R	P2B-IP-315RE
3-15/16	4	ZA-6315-F	ZAS-6315-F	P4B-IP-315R	P4B-IP-315RE

Shaft Size Inches	# of Bolts	Rex 6000 Series		SKF Part #	
		Fixed	Floating	Fixed	Floating
2- 7/16	2	ZAF-6207	ZAFS-6207	SAF22515	SAF22516
2- 7/16	4	ZAF-6207-F	ZAFS-6207-F	FSAF22515	FSAF22516
2- 11/16	2	ZAF-6211	ZAFS-6211	SAF22516	SAF22516
2- 11/16	4	ZAF-6211-F	ZAFS-6211-F	FSAF22516	FSAF22516
2- 15/16	2	ZAF-6215	ZAFS-6215	SAF22517	SAF22517
2- 15/16	4	ZAF-6215-F	ZAFS-6215-F	FSAF22517	FSAF22517
3- 7/16	2	ZAF-6307	ZAFS-6307	SAF22520	SAF22520
3- 7/16	4	ZAF-6307-F	ZAFS-6307-F	FSAF22520	FSAF22520
3- 15/16	4	ZAF-6315-F	ZAFS-6315-F	SAF22522	SAF22522
4- 7/16	4	ZAF-6407Y-F	ZAFS-6407Y-F	SAF22526	SAF22526
4- 15/16	4	ZAF-6415-F	ZAFS-6415-F	SAF22528	SAF22528
5- 7/16	4	ZAF-6507-F	ZAFS-6507-F	SAF22532	SAF22532
5- 15/16	4	ZAF6515-F	ZAF6515-F	SAF22534	SAF22534
6- 7/16	4	ZAF6607-F	ZAF6607-F	SAF22536	SAF22536
6- 15/16	4	ZAF6615-F	ZAF6615-F	SAF22538	SAF22538

Rexnord SHURLOK and Spyglass are registered trademarks of Rexnord Corporation.

IMPERIAL and DODGE are registered trademarks of Baldor Electric Company.

SKF is a trademark of the SKF Group.