



Key Industries:

- Air Handling
- Aggregates
- Construction
- Forestry
- Mining
- Steel
- Wastewater Management

Housing Options:

- Pillow Blocks
- 4-Bolt Flange Blocks
- Piloted Flange Blocks
- Cartridge Blocks
- Take-Up Blocks

Shaft Sizes:

1 15/16" – 6 15/16"

Mounting Type:

- Adapter Mount

General Bearing Information:

- TGIC Polyester Powder Coated Housings
- Super Finished Raceways
- Larger than Standard Rollers
- Field Interchangeable Seal Options
- Adjustable Clearance

Rex 6000 Series SHURLOK Adapter Mounted Roller Bearing


Increase your operation's efficiency and profitability by reducing installation errors, maintenance costs, and downtime. The innovative Rex® 6000 Series SHURLOK® Adapter Mounted Roller Bearing requires less lubrication and is ideal for ISO 14000 compliance.

The bearing's rugged and adaptable design makes it excellent for mining, aggregate production, forest products, and other demanding applications.

A positive locking feature and single housing construction provide easy installation and removal, and enable use of inexpensive commercial grade shafting.

Shurlok Mounts are available in many Rexnord housings for shaft sizes from 1 15/16 inches to 6 15/16 inches. They also have four interchangeable seal options and several auxiliary cap seal configurations to meet each unique application's needs.

ZA 6000

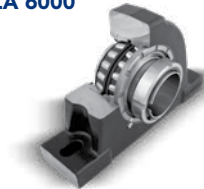

VS

Imperial®



- 25 percent greater shaft grip (on 2 7/16 shaft size) means less vibration and maintenance.
- Quick release feature allows easy removal for maintenance, plus the adapter assembly can be reused.
- Positive Locking System maintains shaft mount tightness, eliminating the need for later mounting inspections.

ZAF 6000



VS

SAF



- Rugged one-piece housing decreases installation/removal time by as much as four times versus SAF models.
- Factory pre-lubricated elements require four times less annual lubrication than SAF models - ISO 14000 friendly.
- Factory pre-set clearances. Solid housed units with factory pre-set clearances reduce installation time by up to four times.

Super-finished Raceways

Provide a cool running, quiet, high speed and high load capacity bearing

Self Aligning Spherical Roller Bearing

Provides a total of four degrees static and dynamic misalignment

Auxiliary End Caps & Four Field Interchangeable Seal Options

Ensures long bearing life through a full range of applications



Roller Elements

Are precision ground and super finished to provide longer bearing life

Adapter Sleeve Assembly

Allows easy installation/removal, plus enables use of commercial grade shafts

Positive Locking System

Allows minimal vibration during operation, therefore not requiring scheduled inspections for snugness of mountings

Rex 6000 Series SHURLOK Roller Bearings are also available in these housings:



Rex 6000 Series Roller Bearing Interchange Examples

| Shaft Size Inches | # of Bolts | Rex 6000 Series | | Dodge Imperial | |
|-------------------|------------|-----------------|------------|----------------|--------------|
| | | Fixed | Floating | Fixed | Floating |
| 1-15/16 | 2 | ZA-6115 | ZAS-6115 | P2B-IP-115R | P2B-IP-115RE |
| 1-15/16 | 4 | ZA-6115-F | ZAS-6115-F | P4B-IP-115R | P4B-IP-115RE |
| 2-13/16 | 2 | ZA-6203 | ZAS-6203 | P2B-IP-203R | P2B-IP-203RE |
| 2-13/16 | 4 | ZA-6203-F | ZAS-6203-F | P4B-IP-203R | P4B-IP-203RE |
| 2-3/8 | 2 | ZA-6206 | ZAS-6206 | P2B-IP-206R | P2B-IP-206RE |
| 2-3/8 | 4 | ZA-6206-F | ZAS-6206-F | P4B-IP-206R | P4B-IP-206RE |
| 2-7/16 | 2 | ZA-6207 | ZAS-6207 | P2B-IP-207R | P2B-IP-207RE |
| 2-7/16 | 4 | ZA-6207-F | ZAS-6207-F | P4B-IP-207R | P4B-IP-207RE |
| 2-11/16 | 2 | ZA-6211 | ZAS-6211 | P2B-IP-211R | P2B-IP-211RE |
| 2-11/16 | 4 | ZA-6211-F | ZAS-6211-F | P4B-IP-211R | P4B-IP-211RE |
| 2-3/4 | 2 | ZA-6212 | ZAS-6212 | P2B-IP-212R | P2B-IP-212RE |
| 2-3/4 | 4 | ZA-6212-F | ZAS-6212-F | P4B-IP-212R | P4B-IP-212RE |
| 2-15/16 | 2 | ZA-6215 | ZAS-6215 | P2B-IP-215R | P2B-IP-215RE |
| 2-15/16 | 4 | ZA-6215-F | ZAS-6215-F | P4B-IP-215R | P4B-IP-215RE |
| 3-3/16 | 2 | ZA-6303 | ZAS-6303 | P2B-IP-303R | P2B-IP-303RE |
| 3-3/16 | 4 | ZA-6303-F | ZAS-6303-F | P4B-IP-303R | P4B-IP-303RE |
| 3-7/16 | 2 | ZA-6307 | ZAS-6307 | P2B-IP-307R | P2B-IP-307RE |
| 3-7/16 | 4 | ZA-6307-F | ZAS-6307-F | P4B-IP-307R | P4B-IP-307RE |
| 3-11/16 | 2 | ZA-6311 | ZAS-6311 | P2B-IP-311R | P2B-IP-311RE |
| 3-11/16 | 4 | ZA-6311-F | ZAS-6311-F | P4B-IP-311R | P4B-IP-311RE |
| 3-15/16 | 2 | ZA-6315 | ZAS-6315 | P2B-IP-315R | P2B-IP-315RE |
| 3-15/16 | 4 | ZA-6315-F | ZAS-6315-F | P4B-IP-315R | P4B-IP-315RE |

| Shaft Size Inches | # of Bolts | Rex 6000 Series | | SKF Part # | |
|-------------------|------------|-----------------|--------------|------------|-----------|
| | | Fixed | Floating | Fixed | Floating |
| 2- 7/16 | 2 | ZAF-6207 | ZAFS-6207 | SAF22515 | SAF22516 |
| 2- 7/16 | 4 | ZAF-6207-F | ZAFS-6207-F | FSAF22515 | FSAF22516 |
| 2- 11/16 | 2 | ZAF-6211 | ZAFS-6211 | SAF22516 | SAF22516 |
| 2- 11/16 | 4 | ZAF-6211-F | ZAFS-6211-F | FSAF22516 | FSAF22516 |
| 2- 15/16 | 2 | ZAF-6215 | ZAFS-6215 | SAF22517 | SAF22517 |
| 2- 15/16 | 4 | ZAF-6215-F | ZAFS-6215-F | FSAF22517 | FSAF22517 |
| 3- 7/16 | 2 | ZAF-6307 | ZAFS-6307 | SAF22520 | SAF22520 |
| 3- 7/16 | 4 | ZAF-6307-F | ZAFS-6307-F | FSAF22520 | FSAF22520 |
| 3- 15/16 | 4 | ZAF-6315-F | ZAFS-6315-F | SAF22522 | SAF22522 |
| 4- 7/16 | 4 | ZAF-6407Y-F | ZAFS-6407Y-F | SAF22526 | SAF22526 |
| 4- 15/16 | 4 | ZAF-6415-F | ZAFS-6415-F | SAF22528 | SAF22528 |
| 5- 7/16 | 4 | ZAF-6507-F | ZAFS-6507-F | SAF22532 | SAF22532 |
| 5- 15/16 | 4 | ZAF6515-F | ZAF6515-F | SAF22534 | SAF22534 |
| 6- 7/16 | 4 | ZAF6607-F | ZAF6607-F | SAF22536 | SAF22536 |
| 6- 15/16 | 4 | ZAF6615-F | ZAF6615-F | SAF22538 | SAF22538 |

REXNORD SHURLOK is a registered trademark of Rexnord Corporation.

IMPERIAL and DODGE are registered trademarks of Baldor Electric Company.

SKF is a trademark of the SKF Group.