



#### **Why Choose Rexnord?**

When it comes to providing highly engineered products that improve productivity and efficiency for industrial applications worldwide, Rexnord is the most reliable in the industry. Our commitment to customer satisfaction and superior value extends to every area of our business.

#### **Delivering Lowest Total Cost of Ownership**

The highest quality products are designed to help prevent equipment downtime, increase productivity and deliver dependable operation.

#### **Valuable Expertise**

An extensive product offering is accompanied by global sales specialists, customer service and maintenance support teams, available anytime.

#### **Solutions to Enhance Ease of Doing Business**

Our commitment to operational excellence means you benefit from getting the right products to the right place at the right time.

## Why Choose Link-Belt Mounted Ball Bearings?

### **Technical Expertise**

Link-Belt® ball bearings are supported by a team of highly experienced application engineers to provide customers with bearing performance analysis and proper bearing selection for optimal application performance.

### **Innovative Attachment Options**

Replacing ball bearings on your equipment should be straight-forward and error-free, so we have developed patented shaft attachment options to improve shaft holding force and simplify installation. The Centrik-Lok™ CL mounting collar provides industry leading shaft grip strength for extended life in high vibration environments such as package and material handling. The SHURLOK® mounting collar provides the installer with a visual indicator that confirms proper installation.

### **Leading Seal Options**

Link-Belt ball bearings offer highly engineered sealing options for a wide range of applications and industries. Our range of seal options allows for the proper balance of protection against contaminants and dynamic bearing performance to reduce premature bearing failure, reduce unplanned downtime and improve overall productivity.

### **Range of Duty**

Link-Belt mounted ball bearings offer the widest range of duty and performance options. We offer a wide variety of housings, seals and mounting options to provide customers with a broad range of product configurations. Combined with our vast component supermarket, Rexnord is able to provide the optimal ball bearing tailored to the specific needs of your application.

### **Availability**

We understand that equipment downtime is not an option for our customers. Rexnord utilizes a network of warehouses and distribution channels to provide inventory coverage for our product offering and provide greater customer satisfaction.





### Wide Range of Duty Options

#### Heavy-Duty



- Shaft sizes up to 4" (102 mm)
- Set screw, eccentric and SHURLOK adapter-mount shaft attachments
- Alignable, precision, deep-groove ball bearings

#### Intermediate-, Standard- and Medium-Duty



- Shaft sizes up to 4" (102 mm)
- Centrik-Lok, set screw and eccentric cam locking collars
- Narrow or wide inner rings
- Light and heavy contact seals

#### Corrosion-Resistant




- Shaft sizes up to 1-15/16" (49 mm)
- Stainless steel bearing insert
- Front and rear double lip seals
- Protective safety caps

### Process & Motion Control Products & Solutions For Your Business

Bearing  
Coupling  
Gear  
Industrial Chain  
Conveying Equipment  
FlatTop  
Product Services

### Industries Served

Aggregates  
Air Handling  
Construction Machinery  
Food & Beverage  
Forest Products  
Material Handling  
Mining  
Pumps & Compressors  
Steel

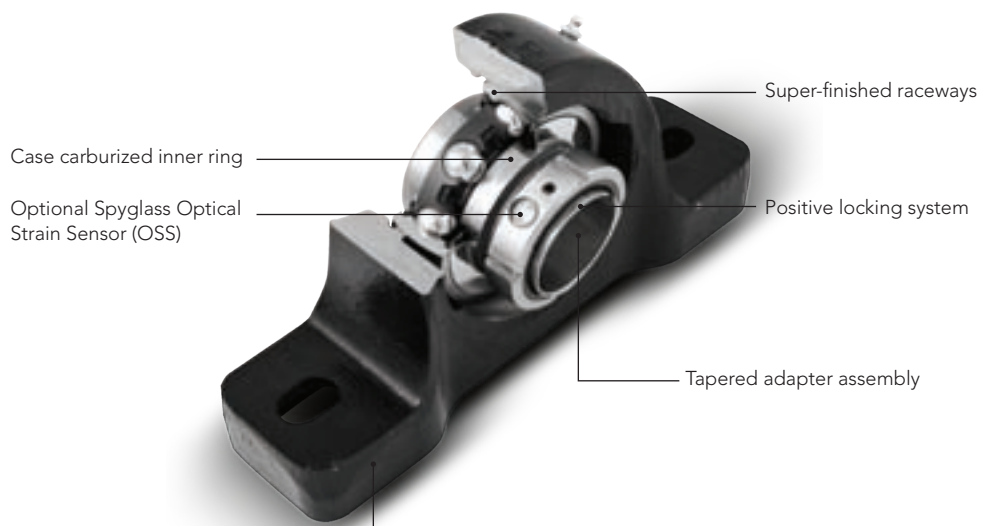

Solid housing ships pre-loaded with the right lubricant for the application