




PRODUCT INFO SHEET

REXNORD® DRY RUN 60 SERIES TABLETOP® CHAIN

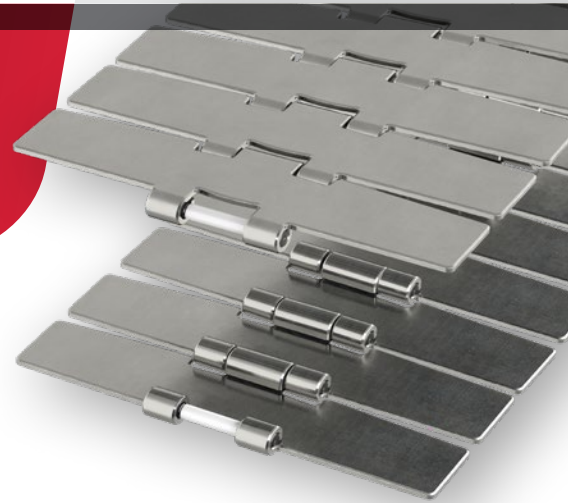

Regal Rexnord is committed to enabling our customers to run dry and reduce water consumption. With the Rexnord Dry Run 60 Series TableTop Chain we are able to provide a complete portfolio of run dry solutions in modular plastic and table top.

ENGINEERED SUSTAINABILITY MEETS METAL TABLETOP

Regal Rexnord has committed years of research and development to bring the benefits of running dry to our Rexnord Metal TableTop portfolio which resulted in the Rexnord Dry Run 60 Series TableTop Chain in 7.5 inch and 3.25 inch width executions. By developing a specialized plastic bushing and pin retention system, the Rexnord Run Dry 60 Series TableTop Chain no longer requires lubrication and avoids excess wear between the hinge and pin as the chain articulates.

NO SWITCHING COSTS TO RUN DRY

By focusing on specialized material development for the hinge of the Rexnord Run Dry 60 Series TableTop Chain, it can offer a run dry solution with the same dimensional properties as our legacy offering. This solution means there is minimal changes needed on the line to begin running dry. Installing and converting your line is as simple as replacing your old chain with the Rexnord Run Dry 60 Series TableTop Chain and then simply turn off the lubrication system.

REDUCE TOTAL COST OF OWNERSHIP & IMPROVE SAFETY

Once the Rexnord Run Dry 60 Series TableTop Chain has been installed, the use of water and costly lubricant is eliminated. By keeping the conveyor line space, operators can enjoy a safe, slip free environment.

PORTFOLIO DESIGNED TO MATCH YOUR NEEDS

Regal Rexnord offers a complete range of curve materials to ensure you get the best performance of your run dry production line. For more information, please contact Application Engineering to ensure you are getting the best performance out of your conveyor.

KEY INDUSTRY

- Beverage

KEY APPLICATIONS


- Beverage Filling Line
- Crate Conveying

SPECIFICATIONS

- Pitch: 1.5 inch (3.81 cm)
- Height: 1.18 inch +/- 0.003 inch (3 mm +/-0.1 mm)

QUESTIONS?

Contact your local Regal Rexnord FlatTop Customer Service Representative

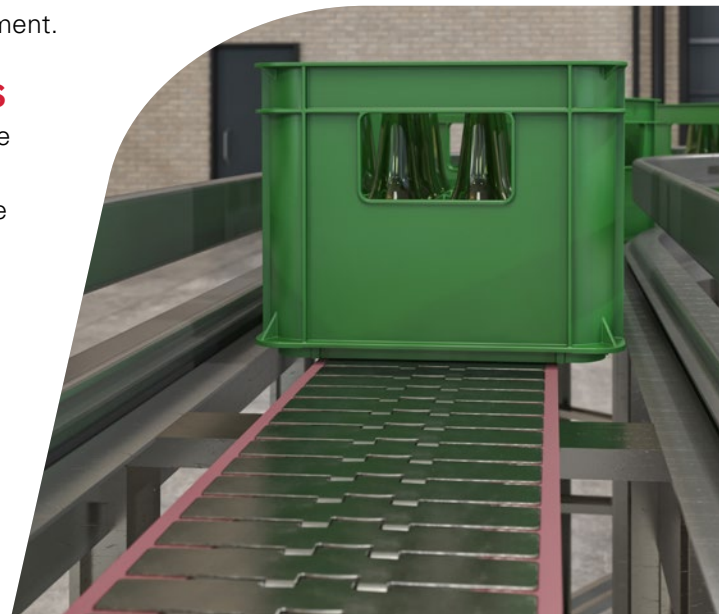

REXNORD® DRY RUN 60 SERIES TABLETOP® CHAIN

Rexnord® Run Dry 60 Series TableTop® Chain Specifications

	Chain Type	Code Number	Temperature Range				Working Load		Approximate Weight		Backflex Radius		
			Fahrenheit		Celsius								
			min	max	min	max	lbs/ft	N/m	lbs/ft ²	Kg/m ²	inch	mm	
			dry	dry	dry	dry							
Heavy Duty Hinge	DR60M75M	10811738	-40 °F	176	-40 °C	80 °C	1574	7000	3,37	5,03	3,94	100	7.5 inch
	DR60S75M	10835549	-40 °F	176	-40 °C	80 °C	1574	7000	3,42	5,10	5,91	150	
Standard Hinge	DR60M72M	10854610	-40 °F	176	-40 °C	80 °C	1349	6000	3,08	4,59	3,94	100	3.25 inch
	DR60S72M	10854609	-40 °F	176	-40 °C	80 °C	1349	6000	3,34	4,99	5,91	150	
	DR60M31M	10829859	-40 °F	176	-40 °C	80 °C	1349	6000	1,17	2,50	3,94	100	
	DR60S31M	10838568	-40 °F	176	-40 °C	80 °C	1349	6000	1,17	2,50	5,91	150	
RubberTop	DR60M75RM	10847610	-40 °F	176	-40 °C	80 °C	1574	7000	3,45	5,14	3,94	100	7.5 inch
	DR60S75RM	10847607	-40 °F	176	-40 °C	80 °C	1574	7000	3,50	5,21	5,91	150	
	DR60M31RM	10847612	-40 °F	176	-40 °C	80 °C	1349	6000	1,71	2,54	3,94	100	3.25 inch
	DR60S31R	10847609	-40 °F	176	-40 °C	80 °C	1349	6000	1,71	2,55	2,95	75	

ENGINEERED SUSTAINABILITY MEETS METAL TABLETOP®

Safety

The elimination of lubricants keep your production floors clean and helps you achieve a safe working environment.

Reduced Water Consumption


Thanks to the Rexnord Run Dry 60 Series TableTop Chain conveyors save up to 9 million liters of water each year.

Noise Reduction

The Rexnord Dry Run 60 Series reduces noise levels in beverage plants to half of the original solution, resulting in a safer work environment for line personnel.

Increased Hygiene

Without lubrication, conveyors are less sensitive to develop mold growth.

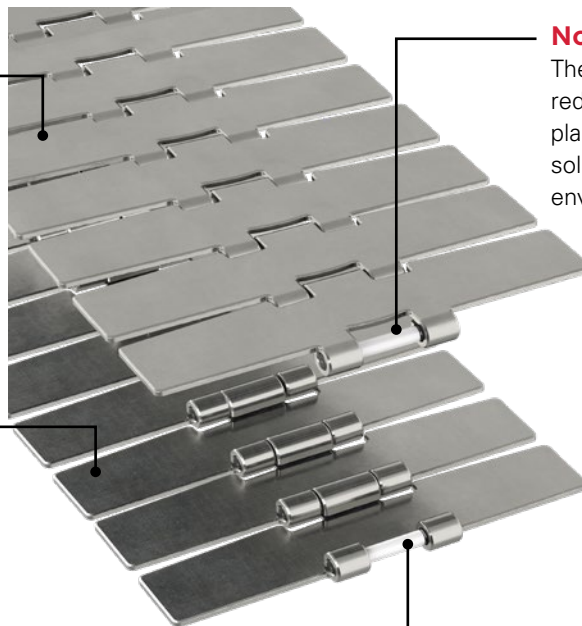

Motion Control Solutions
Regal Rexnord

Contact us: [rexnord.com/contact](https://www.rexnord.com/contact)

[regalrexnord.com](https://www.regalrexnord.com)

The proper selection and application of products and components, including assuring that the product is safe for its intended use, are the responsibility of the customer. To view our Application Considerations, please visit <https://www.regalrexnord.com/Application-Considerations>. To view our Standard Terms and Conditions of Sale, please visit <https://www.regalrexnord.com/Terms-and-Conditions-of-Sale> (which may redirect to other website locations based on product family).

"Regal Rexnord" is not indicative of legal entity. Refer to product purchase documentation for the applicable legal entity. Regal Rexnord, Rexnord, and TableTop are trademarks of Regal Rexnord Corporation or one of its affiliated companies. © 2021, 2022 Regal Rexnord Corporation, All Rights Reserved. MCSSP22132E • Form# FT5-154E

