




# 3120 Series MatTop Chain Universal Bracket

BREAKTHROUGH AUTOMOTIVE SOLUTION

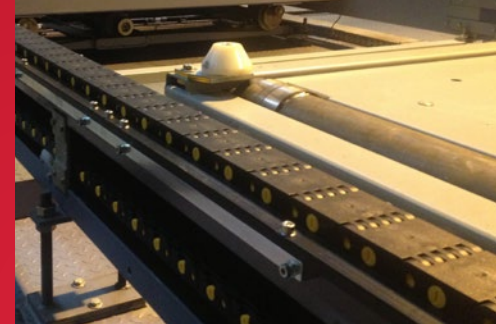

The Rexnord 3120 MatTop® Series Chain offers a maintenance-free chain system widely used in automotive and heavy-duty industrial applications. It offers high strength and stiffness. These attributes provide continuously smooth operation under heavily loaded conditions.

The Rexnord 3120 Series MatTop Chain is designed for industrial-type applications, such as skid handling, people movers, pallet handling and automotive parts handling. The robust design utilizes our patented Twistlock® plug.

## ROBUST DESIGN

The Rexnord 3120 Series MatTop Chain offering is extended with the universal bracket. Based on a stainless steel robust bracket design, the roller brackets are connected to the plastic link in a robust slot, and locked with a spring-clip. The brackets can be installed and removed within seconds, using a standard screwdriver. Customized rollers can be made on request.

## EASY TECHNOLOGY CONVERSION

The 3120 Series MatTop Chain expands the possibilities to easily and economically convert from your existing technology. Reinforced rubber belt applications can be converted to a reliable MatTop technology-handling solution, using the existing conveyor structure, and applying new guides and drive sprockets.

## OPERATION CHARACTERISTICS:

- Insensitive to automotive liquids
- Positive drive sprocket eliminates slippage and prevents the skid from twisting during conveying
- Energy savings due to full plastic chain design which offers reduced weight and low friction
- High stiffness through narrow hinge design and large pin diameter
- No tensioning of the chain is required
- Easy installation and maintenance of chain bracket
- Chain damage can be repaired by replacing a single link at a time
- Brackets can be used to mount other parts, such as pedestals or customized pushers
- Standard roller sizes are available in metric sizes (30 and 60 millimeters); imperial sizes are available on request

**Please contact your  
Rexnord representative  
with any questions:**

**Rexnord FlatTop Europe**  
Einsteinstraat 1, 2691 GV  
's-Gravenzande  
The Netherlands  
Phone: +31 174 445 111  
After Hours Emergency  
Phone: +31 174 445 112

**Rexnord FlatTop North America**  
Phone: 1-262-376-4600

[rexnord.com](http://rexnord.com)



